

THREADED CAST BRONZE FITTINGS

HEX BUSHING

CLASS 125#

Part No. LF Imp	Part No. LF Dom	Part No. Import	Part No. Domestic	Size	Pkg Qty	Approx Weight	A Inches	B Inches	C Inches	H Inches
		66003X01		1/4" x 1/8"	25	.02	0.44	0.26	0.14	0.64
		66004X01		1/2" x 1/8"	25	.08	0.56	0.25	0.19	0.87
LF66004X02	LF76004X02	66004X02	76004X02	1/2" x 1/4"	25	.06	0.56	0.32	0.19	0.87
LF66004X03	LF76004X03	66004X03	76004X03	1/2" x 3/8"	25	.06	0.56	0.41	0.19	0.87
	LF76006X01	66006X01	76006X01	3/4" x 1/8"	25	.15	0.63	0.63	0.25	1.15
LF66006X02	LF76006X02	66006X02	76006X02	3/4" x 1/4"	25	.15	0.63	0.32	0.22	1.15
LF66006X03	LF76006X03	66006X03	76006X03	3/4" x 3/8"	25	.11	0.63	0.36	0.22	1.15
LF66006X04	LF76006X04	66006X04	76006X04	3/4" x 1/2"	25	.11	0.63	0.53	0.22	1.15
LF66010X02	LF76010X02	66010X02	76010X02	1" x 1/4"	25	.20	0.75	0.32	0.30	1.12
	LF76010X03	66010X03	76010X03	1" x 3/8"	25	.20	0.75	0.36	0.30	1.12
LF66010X04	LF76010X04	66010X04	76010X04	1" x 1/2"	25	.20	0.75	0.43	0.25	1.42
LF66010X06	LF66010X06	66010X06	76010X06	1" x 3/4"	25	.20	0.75	0.50	0.25	1.42
	LF76012X02		76012X02	1-1/4" x 1/4"	25	.31	-	-	-	-
	LF76012X03		76012X03	1-1/4" x 3/8"	25	.31	0.80	0.36	0.34	1.12
LF66012X04	LF76012X04	66012X04	76012X04	1-1/4" x 1/2"	25	.31	0.80	0.43	0.34	1.34

THREADED CAST BRONZE FITTINGS


HEX BUSHING CONT. (1)

CLASS 125#

Part No. LF Imp	Part No. LF Dom	Part No. Import	Part No. Domestic	Size	Pkg Qty	Approx Weight	A Inches	B Inches	C Inches	H Inches
LF66012X06	LF76012X06	66012X06	76012X06	1-1/4" x 3/4"	25	.33	0.80	.050	0.28	1.76
LF66012X10	LF76012X10	66012X10	76012X10	1-1/4" x 1"	25	.33	0.80	0.58	0.28	1.76
LF66014X04	LF76014X04	66014X04	76014X04	1-1/2" x 1/2"	25	.55	0.83	0.43	0.37	1.34
LF66014X06	LF76014X06	66014X06	76014X06	1-1/2" x 3/4"	25	.55	0.83	0.50	0.37	1.63
LF66014X10	LF76014X10	66014X10	76014X10	1-1/2" x 1"	25	.35	0.83	0.58	0.31	2.00
LF66014X12	LF76014X12	66014X12	76014X12	1-1/2" x 1-1/4"	25	.35	0.83	0.71	0.31	2.00
	LF76020X02	66020X02	76020X02	2" x 1/4"	10	.69	-	-	-	-
LF66020X04	LF76020X04	66020X04	76020X04	2" x 1/2"	10	.69	0.88	0.43	0.41	1.34
LF66020X06	LF76020X06	66020X06	76020X06	2" x 3/4"	10	.69	0.88	0.50	0.41	1.63
LF66020X10	LF76020X10	66020X10	76020X10	2" x 1"	10	.69	0.88	0.58	0.41	1.95
LF66020X12	LF76020X12	66020X12	76020X12	2" x 1-1/4"	10	.73	0.88	0.67	0.34	2.48
LF66020X14	LF76020X14	66020X14	76020X14	2" x 1-1/2"	10	.73	0.88	0.70	0.34	2.48
	LF76024X10	66024X10	76024X10	2-1/2" x 1"	5	1.08	1.07	0.58	0.44	1.95
	LF76024X12	66024X12	76024X12	2-1/2" x 1-1/4"	5	1.08	1.07	0.67	0.44	2.39
	LF76024X14	66024X14	76024X14	2-1/2" x 1-1/2"	5	1.00	1.07	0.70	0.44	2.68

THREADED CAST BRONZE FITTINGS

HEX BUSHINGS CONT. (2)

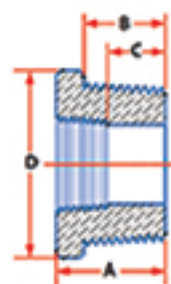

Part No. LF Imp	Part No. LF Dom	Part No. Import	Part No. Domestic	Size	Pkg Qty	Approx Weight	A Inches	B Inches	C Inches	H Inches
	LF76024X20	66024X20	76024X20	2-1/2" x 2"	5	1.00	1.07	0.75	0.37	2.98
	LF76030X06		76030X06	3" x 3/4"	5	1.67	-	-	-	-
	LF76030X10		76030X10	3" x 1"	5	1.67	-	-	-	-
	LF76030X12		76030X12	3" x 1-1/4"	5	1.67	1.13	0.67	0.48	2.39
	LF76030X14	66030X14	76030X14	3" x 1-1/2"	5	1.67	1.13	0.70	0.48	2.68
LF66030X20	LF76030X20	66030X20	76030X20	3" x 2"	5	1.83	1.13	0.75	0.48	3.28
	LF76030X24	66030X24	76030X24	3" x 2-1/2"	5	1.83	1.13	0.92	0.40	3.86
		66040X20		4" x 2"	1	3.02	1.22	0.75	0.60	3.28
		66040X24		4" x 2-1/2"	1	3.30	1.22	0.92	0.60	3.86
	LF76040X30	66040X30	76040X30	4" x 3"	1	3.30	1.22	0.98	0.50	4.62

DOMESTIC AND IMPORTED FITTINGS

Bronze Imported Threaded Fittings

ASTM B62

Alloy

C89833

Domestic Threaded Fittings

ASTM B584

Bronze Bar Stock Threaded Fittings

ASTM B16

Lead-Free Bronze Imported &
Domestic Threaded Fittings

ASTM B584

Alloy

C36000



(800) 257-9559

Fax: (866) 706-5260

sales@trentonpipe.com