


## Extension Piece Fig. 157

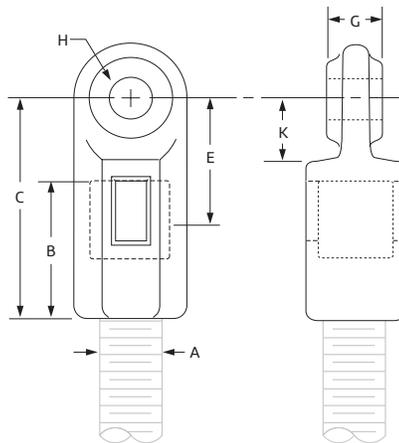

**Size Range:** 3/8" through 7/8"

**Material:** Malleable iron

**Finish:** Plain or Zinc Plated

**Maximum Temperature:** 450° F

**Service:** For attaching hanger rod to various types of building attachments.

**Approvals:** UL Listed (3/8" - 7/8" rod size) and FM Approved (3/8" & 1/2" rod size).

**Installation:** May be used to form an integral part of malleable iron beam clamps Fig. 218.

**Ordering:** Specify rod size, figure number, name and finish.

**Fig. 157: Dimensions (in) • Loads (lbs) • Weight (lbs)**

Rod Size A	Max Load	Weight	B	C	Rod Take-Out - E	G	H	K
3/8	730	0.20	1 1/4	2 1/16	1 1/4	1/2		9/16
1/2	1,350	0.40	1 3/8	2 5/16	1 3/8		1/2	11/16
5/8	1,550	0.44	1 1/2	2 7/16	1 7/16	5/8		3/4
3/4	2,100	0.65	1 3/4	2 7/8	1 11/16			7/8
7/8	2,350	0.78	1 7/8	2	1 3/4	3/4	9/16	



PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	