


## Adjustable Pipe Saddle Fig. 192

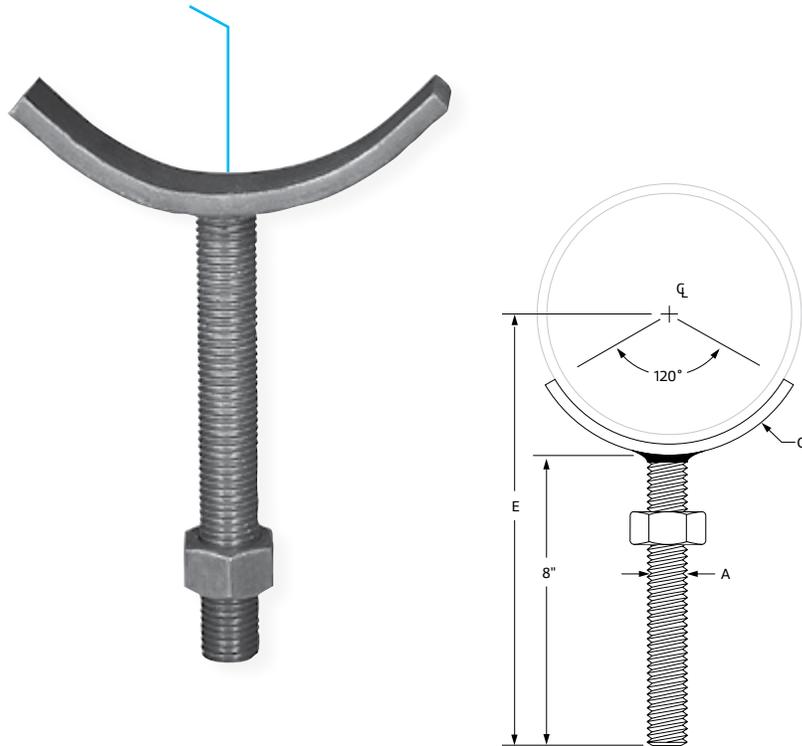

**Size Range:** 2" through 12"

**Material:** Carbon steel

**Finish:** Plain or Zinc Plated  
(Hot-Dip Galvanized optional)

**Service:** Stanchion type support for **stationary** pipe where vertical adjustment is required.

**Approvals:** Complies with Federal Specification A-A-1192A (Type 38), ANSI/MSS SP-69 and MSS SP-58 (Type 38).

**Ordering:** Specify pipe size to be supported, figure number, name and finish.



**Fig. 192: Dimensions (in) • Weight (lbs)**

Pipe Size	Rod Size A	E	G	Weight
2		9 <sup>7</sup> / <sub>16</sub>		1.0
2½		9 <sup>11</sup> / <sub>16</sub>		1.4
3	5/8	10	¼ x 1	1.6
3½		10¼		2.6
4		10½		3.0
5	7/8	11	¼ x 1¼	3.2
6		11 <sup>11</sup> / <sub>16</sub>		4.9
8	1	12 <sup>11</sup> / <sub>16</sub>	3/8 x 1½	6.2
10		13 <sup>7</sup> / <sub>8</sub>		10.5
12	1¼	14 <sup>7</sup> / <sub>8</sub>	½ x 2	11.8

PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	