


MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS

LOCKNUTS

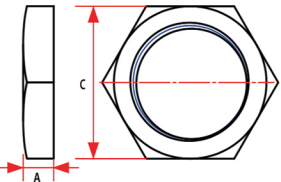

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	A	C
SS304-65901	SS316-65901	1/8"	25	0.0123	0.065	0.66
SS304-65902	SS316-65902	1/4"	25	0.0203	0.243	0.81
SS304-65903	SS316-65903	3/8"	25	0.0311	0.267	0.96
SS304-65904	SS316-65904	1/2"	25	0.0437	0.296	1.13
SS304-65906	SS316-65906	3/4"	25	0.0622	0.326	1.37
SS304-65910	SS316-65910	1"	25	0.1063	0.363	1.38
SS304-65912	SS316-65912	1 1/4"	25	0.1387	0.400	2.00
SS304-65914	SS316-65914	1 1/2"	25	0.1907	0.449	2.25
SS304-65920	SS316-65920	2"	10	0.2844	0.507	2.75
SS304-65924	SS316-65924	2 1/2"	5	0.7665	0.562	3.68
SS304-65930	SS316-65930	3"	5	1.1667	0.643	4.41
SS304-65940	SS316-65940	4"	1	2.1094	0.760	5.54

DOMESTIC AND IMPORTED FITTINGS

Stainless steel fittings are investment castings and Trenton Pipe carries a full size range that is available in stock from 1/8" – 4" in both 304 and 316 grades of stainless steel.

All fittings are threaded to NPT standard in compliance to **ASME B1.20.1**, castings are made in accordance to **ASTM A351** and all fittings are heat treated and tested in accordance to **ASTM A262**.



(800) 257-9559

Fax: (866) 706-5260

sales@trentonpipe.com