


90° Drain Elbow Fig. 7050DR



 - Available galvanized
Available fabricated Schedule 10 only.

Material Specifications

Fabricated Fittings

1 1/4" - 6" are Carbon Steel, A153, Schedule 10

8" - 12" are Carbon Steel, A795/A135/0.188 Wall

Coatings

Rust inhibiting paint

Color: Orange (Standard)

Hot Dipped Zinc Galvanized conforming to ASTM A153 (Optional)

Other available options
(Example: RAL3000 or RAL9000 Series)


Drain elbow has a standard 1" female NPT outlet.

For Listings/Approval Details and Limitations, visit our website at www.asc-es.com or contact an ASC Engineered Solutions™ Sales Representative.



PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	

90° Drain Elbow Fig. 7050DR

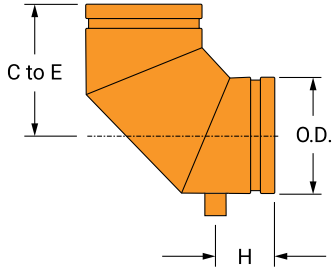

Nominal Size	O.D.	Max. Working Pressure	Dimensions		Approx. Wt. Ea.
			Center to End	H	
In./DN(mm)	In./mm	PSI/bar	In./mm	In./mm	Lbs./kg
1¼ 32	1.660 42.2	300 20.7	2¾ 70	1¾ 44	0.7 0.3
1½ 40	1.900 48.3	300 20.7	2¾ 70	1¾ 44	1.7 0.8
2 50	2.375 60.3	300 20.7	3¼ 83	1¾ 44	2.0 0.9
2½ 65	2.875 73.0	300 20.7	3¾ 95	1⅞ 48	2.5 1.1
3 80	3.500 88.9	300 20.7	4¼ 108	2 51	3.2 1.5
4 100	4.500 114.3	300 20.7	5 127	2¼ 57	4.6 2.1
5 125	5.563 141.3	300 20.7	5½ 140	2⅝ 60	11.5 5.2
6 150	6.625 168.3	300 20.7	6½ 165	2⅝ 60	9.6 4.4
8 200	8.625 219.1	300 20.7	7¾ 197	2½ 64	15.8 7.2
10 250	10.750 273.1	300 20.7	9 229	2¾ 69	48.5 22.0
12 300	12.750 323.9	300 20.7	10 254	2¾ 69	66.0 29.0

Note:

Additional sizes available, see Gruvlok Catalog or contact an ASC Engineered Solutions™ Representative.



asc-es.com

Building connections that last™