


Stainless Steel Braided Hose – 12", 24" and 36" lengths available Fig. 92HS

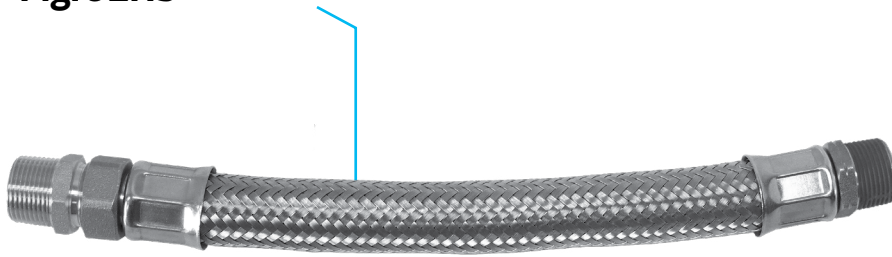


Material Specifications

- 1. Nut**
Brass C36000
- 2. Gasket**
Paper
- 3. Connector**
Stainless Steel AISI304
- 4. Flexible Hose/Inner Pipe**
Stainless Steel/EPDM, AISI304/EPDM
- 5. Screw**
Brass C36000

Features

- Lower risk of leakage
- Fewer field installation joints
- Less installation time and cost
- Fire retardant stainless steel

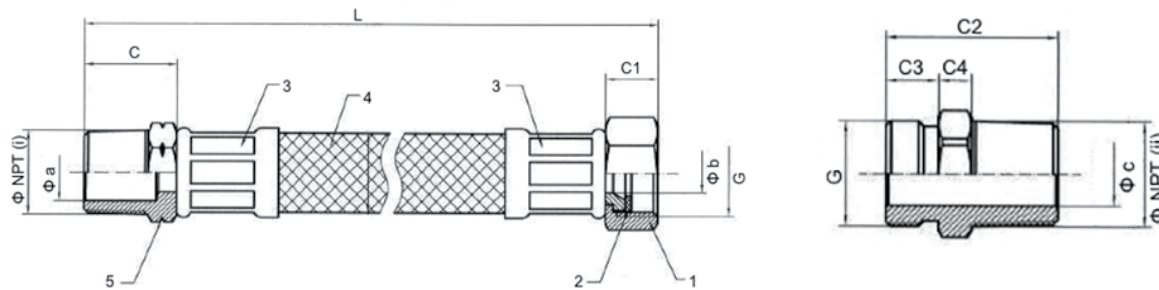

PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	

Stainless Steel Braided Hose – 12", 24" and 36" lengths available Fig. 92HS

Hose Size	øNPT(i)	øNPT(ii)	øa	øb	øc	C	C1	C2	C3	C4	G	L	Approx. Wt. Each
In./mm	In./mm	In./mm	In./mm	In./mm	In./mm	In./mm	In./mm	In./mm	In./mm	In./mm	In./mm	In./mm	Lbs./Kg
1/2 15	1/2 15	1/2 15	0.55 14.0	0.37 9.4	0.49 12.4	0.91 23.1	0.51 13.0	1.34 34.0	0.41 10.4	0.26 6.6	1/2 15	24/36 610/914	.08/1.1 0.36/0.50
3/4 20	3/4 20	3/4 20	0.79 20.1	0.59 15.0	0.69 17.5	0.93 23.9	0.55 14.0	0.46 11.7	0.47 11.9	0.28 7.1	3/4 20	24/36 610/914	1.2/2.0 0.54/0.91
1 25	1 25	1 25	0.94 23.9	0.75 19.1	0.81 20.6	1.1 28.4	0.61 15.5	0.75 19.1	0.57 14.5	0.31 7.9	1 25	24/36 610/914	1.7/2.8 0.77/1.27
1 1/4 32	1 1/4 32	1 1/4 32	1.17 29.8	0.94 23.8	1.00 25.4	1.12 28.4	0.71 18.5	1.85 47.2	0.58 14.8	0.35 9.0	1 1/4 32	24/36 610/914	3.4/3.7 1.52/1.66
1 1/2 40	1 1/2 40	1 1/2 40	1.41 36.0	1.25 31.8	– –	1.18 30.0	0.75 19.0	– –	– –	– –	1 1/2 40	12 305	2.0 0.89
2 50	2 50	2 50	2.09 53.1	2.09 53.1	– –	2.08 52.8	2.08 52.8	– –	– –	– –	2 50	12 305	2.3 1.02

Note:

1 1/2" and 2" sizes are not available with swivel connection.

For additional information on Gruvlok bag and tag coil kit service, contact an ASC Engineered Solutions Representative.



asc-es.com

Building connections that last™