
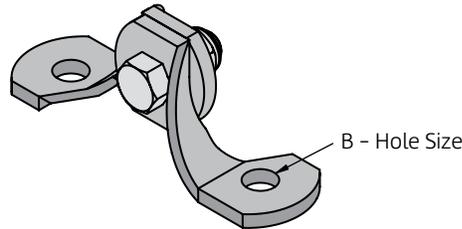


## Hinge Connectors Figs. AS 9402, AS 9403, AS 9404

**AS 9402** EG

### Two-Hole Hinge Connector


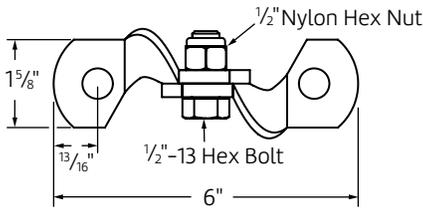


B	Wt./100 Pcs.
1/2"	90
5/8"	88
3/4"	86

Std Pkg 15 - Wt/100 pcs: See chart above.

**AS 9403** EG

### Three-Hole Hinge Connector

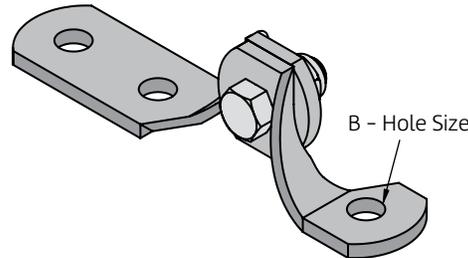
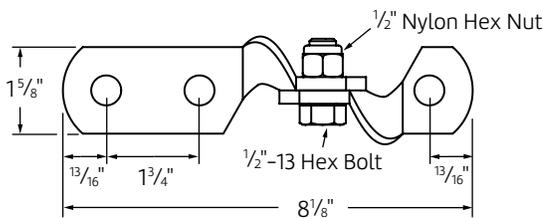


B	Wt./100 Pcs.
1/2"	108
5/8"	107
3/4"	106

Std Pkg 15 - Wt/100 pcs: See chart above.

**AS 9404** EG

### Four-Hole Hinge Connector

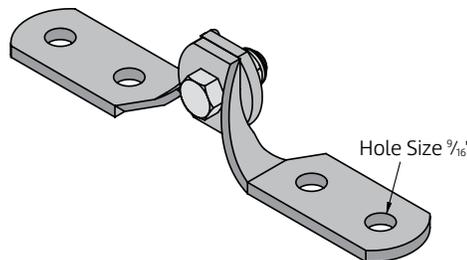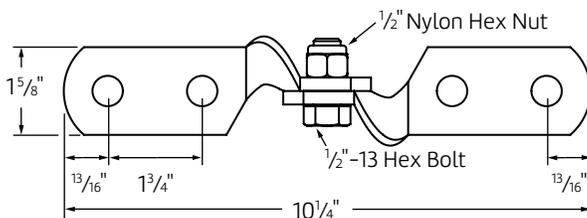

Std Pkg 10 - Wt/100 pcs: 126 Lbs.

**Page notes unless otherwise specified:** 1/4" thick, 1 5/8" wide, holes 9/16" diameter, spaced 1 7/8" on center and 13/16" from end.

#### LEGEND:

**GR:** Powder Coated Supr-Green **EG:** Electro-Galvanized **PG:** Pre-Galvanized **AL:** Aluminum **HG:** Hot Dipped Galvanized **PL:** Plain **SS:** Stainless Steel **ZTC:** Zinc Trivalent Chromium  
Stainless Steel (**SS**), Zinc Trivalent Chromium (**ZTC**) and Hot Dipped Galvanized (**HG**) are specialty finishes. Pricing is located in the Specialty Strut Section of the Anvil-Strut price book.

PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	