



Cushion Strip Fig. AS 3792

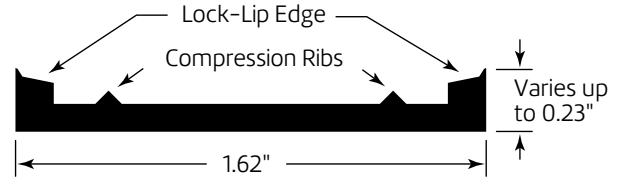

- Manufactured from a thermoplastic elastomer, Cushion Wrap is designed for use from -50°F to 275°F.
- Easy Stocking – Packaged in 20 foot rolls in an E-Z dispenser box for convenience in handling and storage. Cush-A-Strip roll part number is 75100 Cushion Wrap.
- Easy Measuring – Marked in ¼" increments for fast measuring and cutting, while eliminating waste.
- Lock-lip edges ensure that Cushion Wrap will remain in place with a balanced grip.
- Clamps ordered Separately. They are available with a standard bolt and nylon lock nut in steel (electro-dichromate), and stainless steel, in sizes ranging from ¼" tube to 6" pipe. Use C-1100 (EMT, C-1101 (Tube) or C-1102 (Rigid Conduit) pipe clamps.

Cutting Chart

Clamp Size O.D.	Tube Size O.D.	Pipe Size (Nom.)	Cutting Schedule
½"	¼"	-	7/8
5/8"	3/8"	-	1 1/8
¾"	½"	¼"	1 ½
7/8"	5/8"	3/8"	2
1"	¾"	-	2 ¼
1 1/8"	7/8"	½"	3
1 ¼"	1"	¾"	3 ¼
1 3/8"	1 1/8"	-	3 5/8
1 ½"	1 3/16"	-	3 7/8
1 ½"	1 ¼"	1"	4
1 5/8"	1 3/8"	-	4 ½
1 ¾"	1 ½"	-	4 7/8
1 7/8"	1 5/8"	1 ¼"	5 ¼
2"	1 ¾"	-	5 ½
2 1/8"	1 7/8"	1 ½"	6
2 ¼"	2"	-	6 3/8
2 3/8"	2 1/8"	-	6 ¾
2 ½"	2 ¼"	-	7 ¼
2 5/8"	2 3/8"	2"	7 ½
2 ¾"	2 ½"	-	8
3"	2 ¾"	-	8 ¾
3 1/8"	2 7/8"	2 ½"	9 ¼
3 ¼"	3"	-	9 ½
3 ¾"	3 ½"	3"	11
4 ¼"	4"	3 ½"	12 ¼
4 ¾"	4 ½"	4"	14
5 ¾"	-	5"	15 ½
6 7/8"	-	6"	18 ½

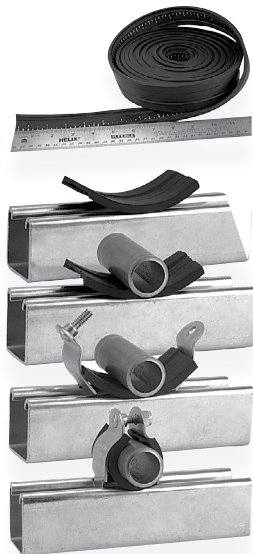

- 1 Cut appropriate length strip using the cutting schedule shown on right.
- 2 Place the pipe on the Cushion Wrap.
- 3 Insert the clamps in the strut.
- 4 Tighten the clamps.

*Gold Plated Steel Clamps Supplied with Fixed Stud and Nylon Lock Nut.

*Stainless Steel Clamps Supplied with fixed Stud and Nylon Lock Nut from ½" through 1 ¼" Sizes and 1 7/8" through 6 7/8" Sizes are Supplied with a Loose Bolt and Hex Nut.

PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	