


One Hole Clamp for O.D. Tubing Figs. AS 1450, AS 3138, AS 270, AS 51

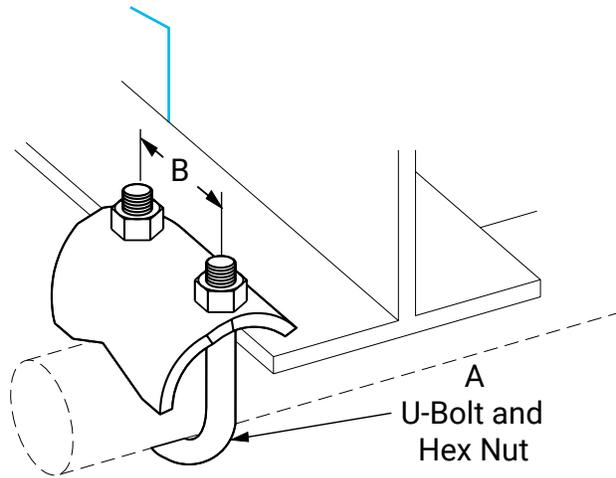

Description

Anvil-Strut Pipe Clamps are all manufactured to fit into the standard openings of 1 $\frac{1}{8}$ " channel to support runs of piping where desired, to secure the pipe in place.

One-Hole Clamp for O.D. Tubing AS 1450 EG

O.D. Size	Steel Gauge	Wt./100 Pcs.	Std. Pkg.
1/4"	16	4	100
3/8"	16	5	100
1/2"	16	6	100
5/8"	14	8	100
3/4"	14	9	100
7/8"	14	10	50
1"	14	11	50

ORDERING: Specify figure number and pipe size.
Std Pkg & Wt/100 pcs: See charts above.

LEGEND:

GR: Powder Coated Supr-Green **EG:** Electro-Galvanized **PG:** Pre-Galvanized **AL:** Aluminum
HG: Hot Dipped Galvanized **PL:** Plain **SS:** Stainless Steel
ZTC: Zinc Trivalent Chromium Stainless Steel (**SS**), Zinc Trivalent Chromium (**ZTC**) and Hot Dipped Galvanized (**HG**) are specialty finishes. Pricing is located in the Specialty Strut Section of the Anvil-Strut price book.




PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	

One Hole Clamp for O.D. Tubing Figs. AS 1450, AS 3138, AS 270, AS 51


Parallel Pipe Clamp AS 3138 EG

Pipe Size	O.D. Size	Wt./100 Pcs.
3/8"	0.675	27
1/2"	0.840	29
3/4"	1.050	30
1"	1.315	31
1 1/4"	1.660	38
1 1/2"	1.990	40
2"	2.375	47
2 1/2"	2.875	66
3"	3.500	78
3 1/2"	4.000	87
4"	4.500	90

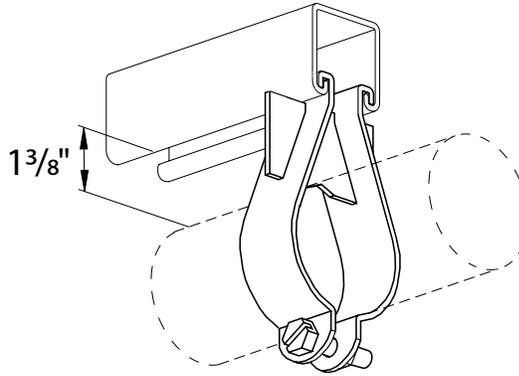

Conduit Clamp AS 270 EG

Diameter	Std. Pkg.	Wt./100 Pcs.
3/8" - 1/2"	50	6
3/4"	50	8
1"	50	9
1 1/4" - 1 1/2"	25	19
2"	50	27

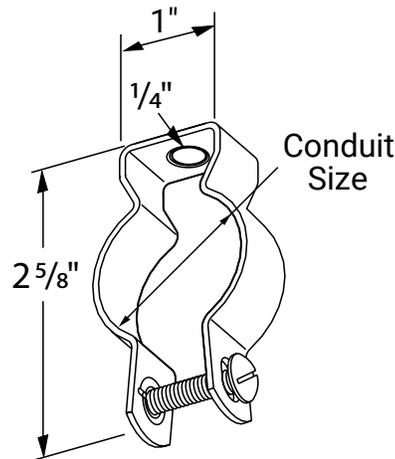


ORDERING: Specify figure number and pipe size.
Std Pkg & Wt./100 pcs: See charts above.

LEGEND:

GR: Powder Coated Supr-Green **EG:** Electro-Galvanized **PG:** Pre-Galvanized **AL:** Aluminum
HG: Hot Dipped Galvanized **PL:** Plain **SS:** Stainless Steel
ZTC: Zinc Trivalent Chromium Stainless Steel (**SS**), Zinc Trivalent Chromium (**ZTC**) and Hot Dipped Galvanized (**HG**) are specialty finishes. Pricing is located in the Specialty Strut Section of the Anvil-Strut price book.

One Hole Clamp for O.D. Tubing Figs. AS 1450, AS 3138, AS 270, AS 51

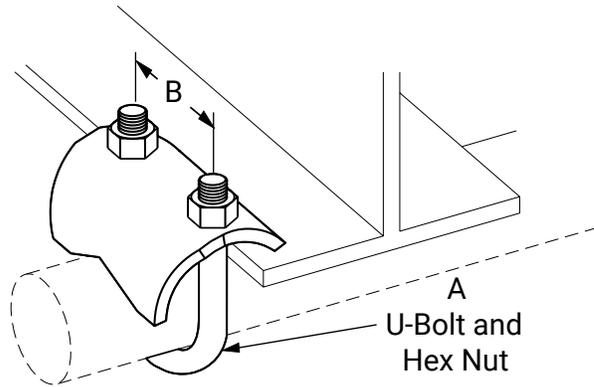

Right Angle Pipe or Conduit Clamp AS 51 EG

Size	A Diameter	B	Wt./100 Pcs.	Std. Pkg.
3/8"	5/16"	15/16"	25	50
1/2"	5/16"	1 3/16"	41	50
3/4"	5/16"	1 7/16"	42	50
1"	5/16"	1 11/16"	47	50
1 1/4"	5/16"	2"	54	50
1 1/2"	5/16"	2 3/8"	57	50
2"	3/8"	2 3/16"	85	50
2 1/2"	3/8"	3 3/8"	106	50
3"	3/8"	4 1/8"	110	25
3 1/2"	3/8"	4 5/8"	128	50
4"	3/8"	5 1/8"	140	50

ORDERING: Specify figure number and pipe size.
Std Pkg & Wt/100 pcs: See charts above.

LEGEND:

GR: Powder Coated Supr-Green **EG:** Electro-Galvanized **PG:** Pre-Galvanized **AL:** Aluminum
HG: Hot Dipped Galvanized **PL:** Plain **SS:** Stainless Steel
ZTC: Zinc Trivalent Chromium Stainless Steel (**SS**), Zinc Trivalent Chromium (**ZTC**) and Hot Dipped Galvanized (**HG**) are specialty finishes. Pricing is located in the Specialty Strut Section of the Anvil-Strut price book.