
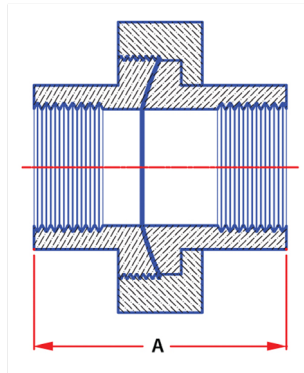


Domestic Lead-Free Bronze 125# Threaded Union Fig. 2330

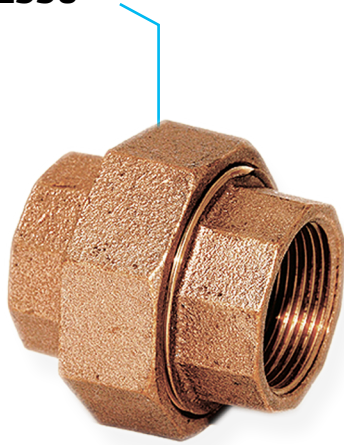

Material Specifications

Domestic Threaded Fittings
ASTM B584

Lead-Free Bronze Domestic Threaded Fittings
ASTM B584

Alloy
C89833

Bronze Bar Stock Threaded Fittings
ASTM B16

Alloy
C36000

Dimensions

| Size | Pkg. Qty. | Approx. Weight | A Inches |
|--------|-----------|----------------|-------------|
| 1/8" | - | .14 | - |
| 1/4" | 25 | .19 | 1.44 |
| 3/8" | 25 | .36 | 1.63 |
| 1/2" | 10 | .41 | 1.81 |
| 3/4" | 25 | .63 | 2.0 |
| 1" | 10 | 1.14 | 2.19 |
| 1 1/4" | - | 1.43 | 2.44 |
| 1 1/2" | - | 2.06 | 2.63 |
| 2" | - | 3.14 | 2.94 |
| 2 1/2" | - | 5.00 | - |
| 3" | 5 | 6.7 | - |



| PROJECT INFORMATION | APPROVAL STAMP |
|---------------------|-------------------|
| Project: | Approved |
| Address: | Approved as noted |
| Contractor: | Not approved |
| Engineer: | Remarks: |
| Submittal Date: | |
| Notes 1: | |
| Notes 2: | |