

# Commercial Flexible Sprinkler Hoses



Tall Hoses  
Fig. 20XXT



- Bend Radius** UL = 3" | FM = 8"
- Pressure Rating** 175 psi
- Hose Lengths** 24", 36", 48", 60", 72"
- Outlet Sizes** 1/2, 3/4 FNPT
- Inlet Nipples** 1" MNPT
- Bracket Options** BKT-MPO – Standard  
BKT-ADO  
BKT-MPT
- Elbow Hoses** 20XXET – 5.65" Elbow  
20XXE – 1.5", 3", 4" Elbow
- High Pressure** 20XXH & 20XXHE 300psi Hoses

UL Listed Equivalent Lengths (1/2" Outlet)		
36" Hose	48" Hose	72" Hose
16 ft	24 ft	35 ft

Superflex® Hoses  
Fig. 20XXSF & 20XXSF-SLT




- Bend Radius** UL = 2" | FM = 7"
- Pressure Rating** 175 psi
- Hose Lengths** 36", 48", 72"
- Outlet Sizes** 1/2, 3/4 FNPT
- Inlet Nipples** 1" MNPT
- Bracket Options** 1" SLT w/ FP74 Coupling  
BKT-ADO  
BKT-MPT
- Confined Space** 20XXSF-CS: 4" Drop  
20XXSF-CS-SLT: 4" Drop w/ SLT

One hose for Straight & Elbow applications

UL Listed Equivalent Lengths (1/2" Outlet)		
36" Hose	48" Hose	72" Hose
30 ft	47 ft	71 ft

1 1/4 Full Flow Hoses  
Fig. 20XXF

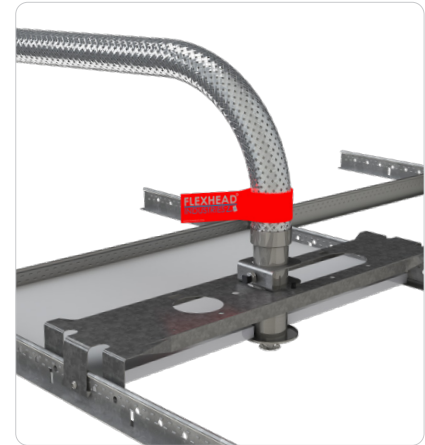


- Bend Radius** FM = 7"
- Pressure Rating** 175 psi
- Hose Lengths** 36", 48", 72"
- Outlet Sizes** 1/2, 3/4, 1 FNPT
- Inlet Nipples** 1 1/4" MNPT
- Bracket Options** 1 1/4" Grooved (20XXFG)  
1 1/4" SLT (20XXF-SLT)  
BKT-MPT – 24" Length  
(Shown Above)

FM Approved Equivalent Lengths (5.6 K)		
36" Hose	48" Hose	72" Hose
4.1 ft	5.4 ft	8.0 ft

All FlexHead hoses are 100% leak tested prior to shipment.

Open Hub Brackets  
Fig. BKT-MPO & BKT-ADO

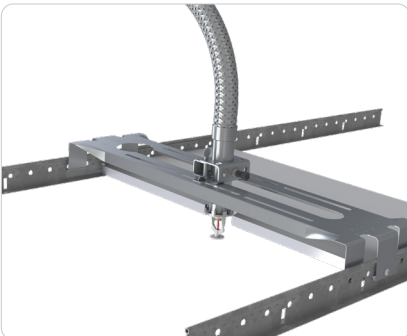

- BKT-MPO Length** 24"
- BKT-ADO Lengths** 16", 24", 30", 48"

Multi-Position Tall Bracket  
Fig. BKT-MPT



- Bracket Lengths** 14.5", 16", 24"
- One Bracket - Adjustable in Length



asc-es.com

Building connections that last™

Ultra SprinkFlex® Hoses  
Fig. HB-1



- Bend Radius** UL = 2" | FM = 7"
- Pressure Rating** 175 psi
- Hose Lengths** 28", 40", 48", 59", 71"
- Outlet Sizes** ½, ¾ FNPT
- Inlet Nipples** 1" MNPT – Standard  
1" Grooved\*  
1" Welded\*
- Bracket Options** BKT-IPT – Standard  
BKT-SFO-4 – FM Only
- Drop Options** 4", 7", 13" Outlet Drops\*
- Fitting Options** Elbow Fitting\*, Hanger Fitting\*

UL Listed Equivalent Lengths (½" Outlet)		
40" Hose	48" Hose	71" Hose
20 ft	34 ft	56 ft

SprinkFlex® Braided Hoses  
Fig. HB-7



- Bend Radius** UL = 3" | FM = 8"
- Pressure Rating** 175 psi
- Hose Lengths** 28", 40", 48", 59", 71"
- Outlet Sizes** ½, ¾ FNPT (7" Drop)
- Inlet Nipples** 1" MNPT – Standard
- Bracket Options** BKT-IPT – Standard  
BKT-SFO-4 – FM Only
- Elbow Options** 4.8", 6.3" Elbow Drops\*
- Non-Braided** HN-7 Non-Braided Hoses (UL)

UL Listed Equivalent Lengths (½" Outlet)		
40" Hose	48" Hose	71" Hose
52 ft	64 ft	94 ft

SprinkFlex® Braided Hoses  
Fig. SFB-4



- Bend Radius** UL = 3" | FM = 8"
- Pressure Rating** 175 psi
- Hose Lengths** 28", 40", 48", 59", 71"
- Outlet Sizes** ½, ¾ FNPT (4" Drop)
- Inlet Nipples** 1" MNPT – Standard
- Bracket Options** BKT-SFO-4 - Standard
- Elbow Options** 3.5", 4.8" Elbow Drops\*
- Non-Braided** SFN-4 Non-Braided Hoses (UL)

UL Listed Equivalent Lengths (½" Outlet)		
40" Hose	48" Hose	71" Hose
52 ft	64 ft	94 ft

\*All SprinkFlex HB1, HB-7, & SFB-4 component options are sold separately.

Infinite Position Tall Brackets  
Fig. BKT-IPT



- Bracket Lengths** 24" & 48"
- Hose Listings** HB-1 (UL/FM)  
HB-7 (UL/FM)  
HN-7 (UL)  
SFB-4 (FM) – Concealed Heads
- Applications** Suspended Ceilings  
Wood & Steel Framing

Open Brackets  
Fig. BKT-SFO-4



- Bracket Lengths** 24" & 48"
- Hose Listings** SFB-4 (UL/FM)  
SFN-4 (UL)  
HB-7 (FM)  
HB-1 (FM)
- Applications** Suspended Ceilings  
Wood & Steel Framing



asc-es.com

Building connections that last™