


## HBM-Support with Steel Channel HBM Series PG

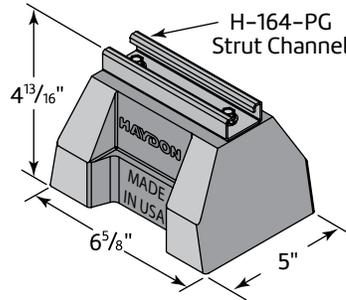

### Specifications

- HBM Series H-Block Mini Support with  $1\frac{3}{16}$ " H-164 Channel, or  $1\frac{5}{8}$ " H-132 Channel

### Materials


- 100% recycled rubber, UV resistant

A cost-effective method for mounting and supporting single pipe applications without losing strength and integrity.

### HBM-Support with $1\frac{3}{16}$ " H-164 Pre-Galv Steel Channel

Model No.	Height	Width	Base Length	Weight (Lbs.)	Uniform Load Capacity (Lbs.)*
HBM-5-H-164-PG	4 $\frac{13}{16}$ " (122 mm)	5" (127 mm)	6 $\frac{5}{8}$ " (168 mm)	2.90	400*

\*This load is only for the capacity of the components in this assembly. Please consult roofing manufacturer or engineer for roof load capacity.

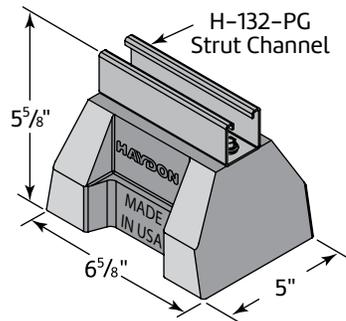

### HBM-Support with $1\frac{5}{8}$ " H-132 Pre-Galv Steel Channel

Model No.	Height	Width	Base Length	Weight (Lbs.)	Uniform Load Capacity (Lbs.)*
HBM-5-H-132-PG	5 $\frac{5}{8}$ " (147 mm)	5" (127 mm)	6 $\frac{5}{8}$ " (168 mm)	3.40	400*

\*This load is only for the capacity of the components in this assembly. Please consult roofing manufacturer or engineer for roof load capacity.

#### LEGEND:

PG: Pre-Galvanized • HG: Hot Dipped Galvanized

Pricing is located in the ASC Engineered Solutions™ H-Block price book.

PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	