


Hinged Pipe Clamp Series HBM-HPC Series, PG

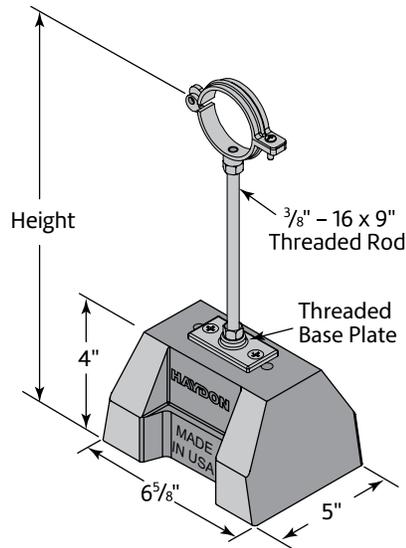

A cost-effective method for mounting and supporting single pipe applications without losing strength and integrity.

Specifications:

HBM-Hinged Pipe Clamp Series

H-Block Mini Support with:

Threaded Rod and Hinged Pipe Clamp

Material:

100% recycled rubber, UV resistant

HBM-Hinged Pipe Clamp Series

Model No.	Height	Width	Base Length	Weight (Lbs)	Uniform Load Capacity (Lbs)*
HBM-HPC-1/2 IN-EG				2.70	
HBM-HPC-3/4 IN-EG				2.80	
HBM-HPC-1 IN-EG	10" - 12"	5"	6 ⁵ / ₈ "	2.90	125*
HBM-HPC-1-1/4 IN-EG	(254mm - 305 mm)	(127 mm)	(168 mm)	3.0	
HBM-HPC-1-1/2 IN-EG				3.10	
HBM-HPC-2 IN-EG				3.30	

*This load is only for the capacity of the components in this assembly. Please consult roofing manufacturer or engineer for roof load capacity.

LEGEND:

PG: Pre-Galvanized **HG:** Hot Dipped Galvanized

Pricing is located in the ASC Engineered Solutions™ H-Block price book.

PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	