


## HBS-Base Rubber Support – Base Only HBS-Standard-Base Only

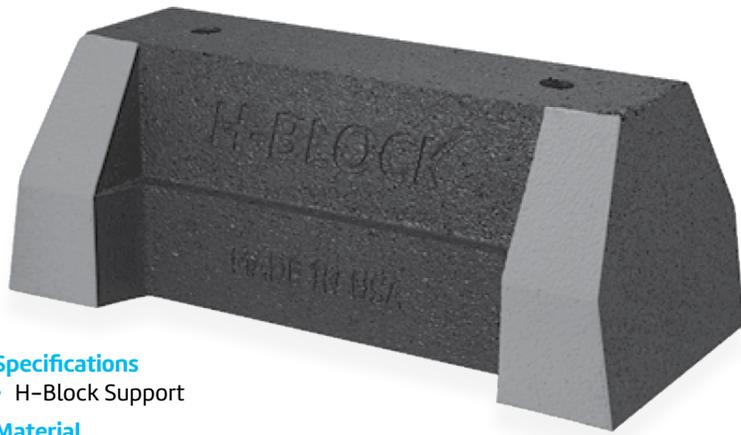

### Specifications

- H-Block Support

### Material


- 100% recycled rubber, UV resistant



**Base Area Shown** = 33.1 Sq. In.

- For use in bearing calculations

The **HBS-Base Series** is UV resistant and suitable for installation on most types of roofing material or other flat surfaces. Can be used as a curb (sleeper) replacement. Screw fasteners can be used to attach one or two hole pipe straps or a piece of strut (not included).

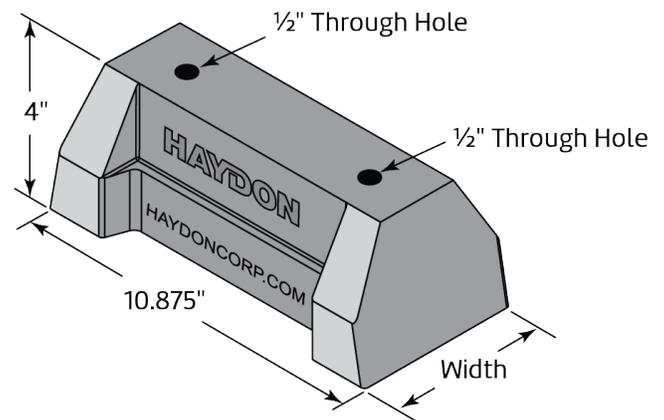

### HBS-Base Rubber Support-Base Only

Model No.	Height	Width	Base Length	Weight (Lbs.)	Uniform Load Capacity (Lbs.)*
HBS-Standard-Base Only	4" (101 mm)	5" (127 mm)	10 <sup>7</sup> / <sub>8</sub> " (276 mm)	4.80 lbs.	1,500*

\* This load is only for the capacity of the components in this assembly. Please consult roofing manufacturer or engineer for roof load capacity.

\* Safety Factor of 3, load based on actual lab testing.

### LEGEND:

PG: Pre-Galvanized • HG: Hot Dipped Galvanized  
Pricing is located in the ASC Engineered Solutions™ H-Block price book.



PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	