

Kennedy Valve Solutions for Fire Protection Systems



UL/FM Flanged,
Grooved & Wafer
Check Valves



UL/FM Grooved
& Wafer Butterfly
Valves




UL/FM Indicator
Posts



Series 5000, UL/FM
Resilient Wedge Gate
Valves, 350 psi



Series 7000, UL/FM,
AWWA C515, Resilient
Wedge Gate Valves

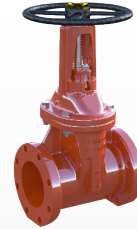

Series 8000, UL/FM,
AWWA C509, Resilient
Wedge Gate Valves



About the Product

Description

ASC Engineered Solutions™ is the master distributor of Kennedy Valves for the fire protection industry. We offer one of the broadest lines of UL/FM valves and indicator posts in the market that provide reliable, cost-effective and innovative solutions you can trust to protect your property.

Product Line

- UL/FM Indicator Posts
- UL/FM Flanged, Grooved & Wafer Check Valves
- UL/FM Grooved & Wafer Butterfly Valves
- Series 5000, UL/FM Resilient Wedge Gate Valves, 350 psi
- Series 7000, UL/FM, AWWA C515, Resilient Wedge Gate Valves
- Series 8000, UL/FM, AWWA C509, Resilient Wedge Gate Valves

Please contact your local ASC Engineered Solutions sales representative.



asc-es.com

Building connections that last™

UL/FM Resilient Wedge Gate Valves

Rubber Encapsulated Wedge

Product	End Connection	Pressure Rating	Features
Non-Rising Stem		AWWA C515 [C509: 2 1/2" & 3"]	
Series 5000	Flanged	350 psi	Available with & without a post plate
Series 7000	Flanged	200 psi (UL/FM). 250 psi (AWWA).	Available with & without a post plate
Series 7000	Grooved	200 psi (UL/FM). 250 psi (AWWA).	Available with & without a post plate
Series 5000	Mechanical Joint (MJ)	350 psi	Available with & without a post plate
Series 7000	Mechanical Joint (MJ)	200 psi (UL/FM). 250 psi (AWWA).	Available with & without a post plate
Series 7000	Flange x Groove	200 psi (UL/FM). 250 psi (AWWA).	Available with & without a post plate
Series 5000	Flange x MJ	350 psi	Available with & without a post plate
Series 7000	Flange x MJ	200 psi (UL/FM). 250 psi (AWWA).	Available with & without a post plate
Series 7000	Threaded (3" only)	200 psi (UL/FM). 250 psi (AWWA).	Available with & without a post plate
Outside Screw and Yoke		AWWA C515 [C509: 2 1/2" & 3"]	
Series 5000	Flanged	350 psi	
Series 7000	Flanged	200 psi (UL/FM). 250 psi (AWWA).	Available with & without a factory installed tamper switch
Series 5000	Grooved	350 psi	
Series 7000	Grooved	200 psi (UL/FM). 250 psi (AWWA).	Available with & without a factory installed tamper switch
Series 5000	Flange x Groove	350 psi	
Series 7000	Flange x Groove	200 psi (UL/FM). 250 psi (AWWA).	Available with & without a factory installed tamper switch
Series 7000	Threaded	200 psi (UL/FM). 250 psi (AWWA).	Available with & without a factory installed tamper switch
Outside Screw and Yoke		AWWA C509	
Series 8000	Threaded (2" & 3" only)	200 psi (UL/FM)	
Series 8000	Flanged	200 psi (UL/FM)	Available with & without a factory installed tamper switch

UL/FM Butterfly Valves

Rubber Encapsulated Disc

Series KVG300C	Grooved	300 psi	Normally Closed
Series KVG300E [8" KV02G]	Grooved	300 psi	Extended Body, Normally Open
Series KVG300EC	Grooved	300 psi	Extended Body, Normally Closed
Series KVV300 [8" KV01W]	Wafer	300 psi	Normally Open
Series KVV300C	Wafer	300 psi	Normally Closed

UL/FM Check Valves

Rubber Seated

Series KV1126A	Flanged	175 psi	Swing Check Valve
Series KV806	Wafer	300 psi	Wafer, Spring Check Valve

UL/FM Indicator Posts

Series KV2945A	Vertical	Four Adjustable Sizes	
Series KV2945W	Wall		



asc-es.com

Building connections that last™

