

Fig. Klo-Shure® Strut Mounted Insulation Coupling used with Fiberglass Insulation



Material Specifications

- For iron pipe and copper tube sizes
- Use with fiberglass insulation

Klo-Shure® Strut Mounted parts include the Klo-Shure® Coupling, clamp halves with welded fastener and locknut.


Materials

Clamp: 1008-1018 Carbon Steel
Coupling: High Strength TPO Plastic

Approvals

- UL 2043 Fire Test for Heat and Visible Smoke Release
- 25/50 Flame Spread / Smoke Development Index.

Note: Klo-Shure® ID equals iron pipe and copper tube OD. Chart indicates coupling sizes currently available from Klo-Shure®. Service Temperature -65°F to 275°F.

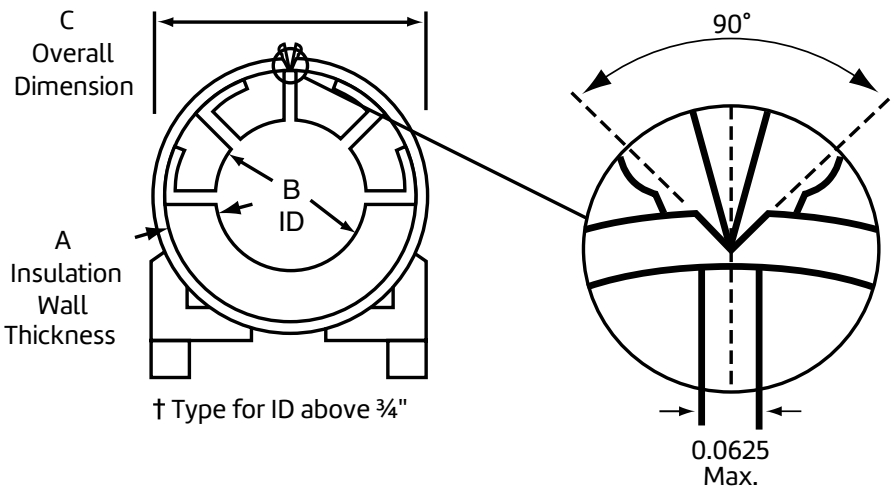

PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	

Fig. Klo-Shure® Strut Mounted Insulation Coupling used with Fiberglass Insulation

A Insulation Wall Thickness	Klo-Shure Part No.	Nominal Steel Pipe Size	B Klo-Shure ID NPS OD	C Overall Dimension	Std. Pkg
Klo-Shure Mounted Coupling for ½" wall insulation	924084	½"	0.84" ID	2.025	20
	924105	¾"	1.05" ID	2.285	20
	924131	1"	1.315" ID	2.500	10
	924166	1¼"	1.66" ID	2.845	10
	924190	1½"	1.90" ID	3.285	10
Klo-Shure Strut Mounted Coupling for 1" wall insulation	928084	½"	0.84" ID	3.008	10
	928105	¾"	1.05" ID	3.008	10
	928131	1"	1.315" ID	3.638	10
	928166	1¼"	1.66" ID	3.638	10
	928190	1½"	1.90" ID	4.138	10
	928237	2"	2.375" ID	4.648	10
Klo-Shure Strut Mounted Coupling for 1½" wall insulation	928287	2½"	2.875" ID	5.138	10
	929084	½"	0.84" ID	4.138	10
	929105	¾"	1.05" ID	4.138	10
	929131	1"	1.315" ID	4.648	10
	929166	1¼"	1.66" ID	5.138	10
929190	1½"	1.90" ID	5.138	10	



asc-es.com

Building connections that last™

Fig. Klo-Shure® Strut Mounted Insulation Coupling used with Fiberglass Insulation

A Insulation Wall Thickness	Klo-Shure Part No.	B Klo-Shure ID Tube OD	C Overall Dimension	Std. Pkg
Klo-Shure-Strut Mounted Coupling for ½" wall insulation	924062	⅝" ID	1.785	20
	924087	⅞" ID	2.025	20
	924112	1⅛" ID	2.285	20
	924137	1⅜" ID	2.500	10
	924162	1⅝" ID	2.845	10
	924212	2⅛" ID	3.285	10
Klo-Shure-Strut Mounted Coupling for 1" wall insulation	928062	⅝" ID	3.008	10
	928087	⅞" ID	3.008	10
	928112	1⅛" ID	3.008	10
	928137	1⅜" ID	3.638	10
	928162	1⅝" ID	3.638	10
	928212	2⅛" ID	4.138	10
	928262	2⅝" ID	4.648	10
Klo-Shure-Strut Mounted Coupling for 1½" wall insulation	928312	3⅛" ID	5.138	10
	929087	⅞" ID	4.138	10
	929112	1⅛" ID	4.138	10
	929137	1⅜" ID	4.648	10
	929162	1⅝" ID	4.648	10
	929212	2⅛" ID	5.138	10



asc-es.com

Building connections that last™