
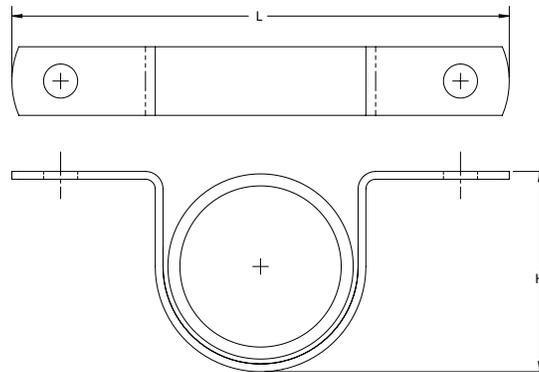


Light Duty Copper Plated Two-Hole Pipe Strap Fig. 026CTG

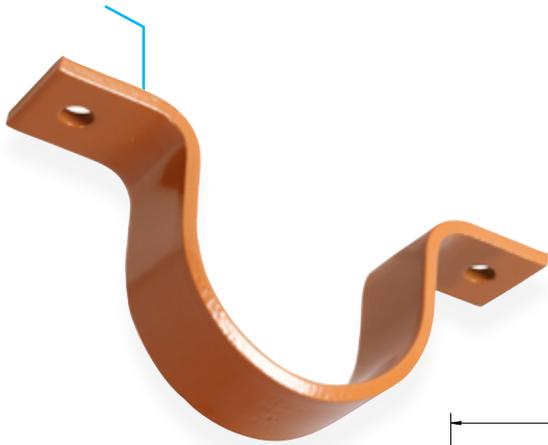

Size Range: ¼" through 4" CTS
Material: Carbon Steel
Finish: Epoxy coated
Service: Recommended for the suspension of stationary copper tube.
Maximum Temperature: 450° F
Approvals: MSS SP-58 (Type-26)
Ordering: Nominal copper pipe size and figure number.



Fig. 026CTG: Dimensions (in) Loads (lbs) • Height/Length (in)

Pipe Size	Max Load w/ Lag Screws	Max Load w/ Bolt to Steel	H Overall Height	Length
¼	150	205	½	3 ⁵ / ₈
½	150	205	¾	4
¾	150	205	1	4 ³ / ₈
1	150	205	1¼	4¾
1¼	159	205	1½	5
1½	150	205	1¾	5 ³ / ₈
2	150	205	2 ⁵ / ₁₆	6 ³ / ₈
2½	150	205	2 ¹⁵ / ₁₆	6 ¹³ / ₁₆
3	225	305	3 ⁷ / ₁₆	7 ¹⁵ / ₁₆
4	225	305	3 ¹³ / ₁₆	8 ³ / ₈

PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	