
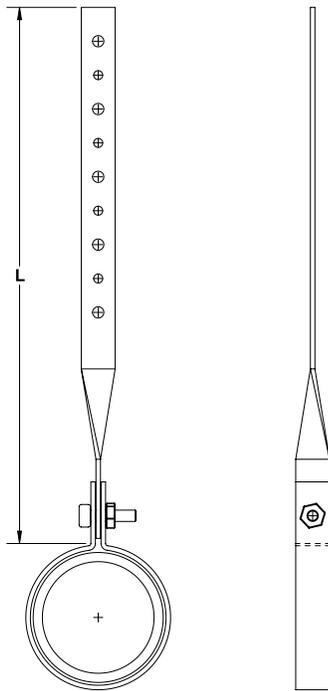


Light Duty DWVG Hanger Fig. DWVG

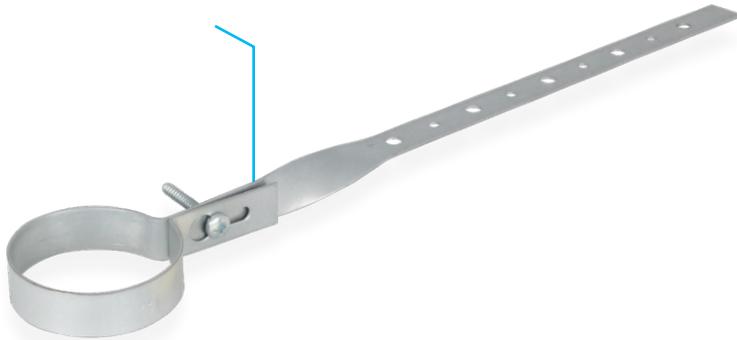

Size Range: 1½" through 4" NPS

Material: Carbon steel

Finish: Electro-Galvanized

Service: Pipe hanger or restraint for DWV pipe.

Installation: Loosen set screw, open hanger, wrap hanger around pipe, close and tighten fastener at slotted hole, fasten to structure with two fasteners using desired mounting holes.

Features:

- Allows for easy adjustability of elevation
- Perfect for use with ABS or PVC plastic DWV pipe

Ordering: Nominal pipe size and figure number.

Notes:

- Set screw requires Phillip's head screwdriver.

Fig. DWVG: Dimensions (in) • Loads (lbs)

Pipe Size	Max Load	Length
1½	150	12
2	150	12
3	200	12
4	250	12



PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	