


## Light Duty Two-Hole Pipe Strap Fig. 026G

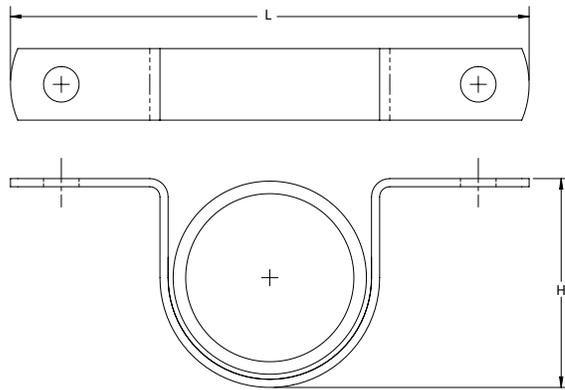

**Size Range:** ¼" through 4"

**Material:** Carbon Steel

**Finish:** Electro-Galvanized

**Service:** Recommended for the suspension of stationary NPS steel pipe.

**Maximum Temperature:** 450° F

**Approvals:** MSS SP-58 (Type-26)

**Ordering:** Nominal pipe size and figure number.



**Fig. 026G: Dimensions (in) Loads (lbs) • Height/Length (in)**

Pipe Size	Max Load w/ Lag Screws	Max Load w/ Bolt to Steel	H Overall Height	Length
¼	150	205	5/8	2 <sup>15</sup> / <sub>16</sub>
½	150	205	7/8	3¼
¾	150	205	1⅛	3 <sup>7</sup> / <sub>16</sub>
1	150	205	1 <sup>3</sup> / <sub>8</sub>	3 <sup>13</sup> / <sub>16</sub>
1¼	159	205	1¾	4 <sup>1</sup> / <sub>8</sub>
1½	150	205	2	4 <sup>3</sup> / <sub>8</sub>
2	150	205	2 <sup>7</sup> / <sub>16</sub>	4 <sup>13</sup> / <sub>16</sub>
2½	225	305	2 <sup>15</sup> / <sub>16</sub>	5 <sup>5</sup> / <sub>16</sub>
3	225	305	3 <sup>9</sup> / <sub>16</sub>	5 <sup>15</sup> / <sub>16</sub>
4	225	305	4 <sup>9</sup> / <sub>16</sub>	7

PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	