

Building connections that last™



Series 52

PVC Expandble Repair Coupling





Galvanized Compression Coupling SCI® Series 2948



Features

- Max. 150 psi @ 73° F
- Iron pipe sizes
- Certified to NSF/ANSI 14 / Annex G Lead-Free
- Cold water use only

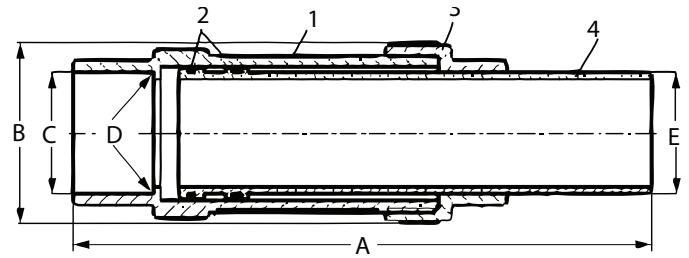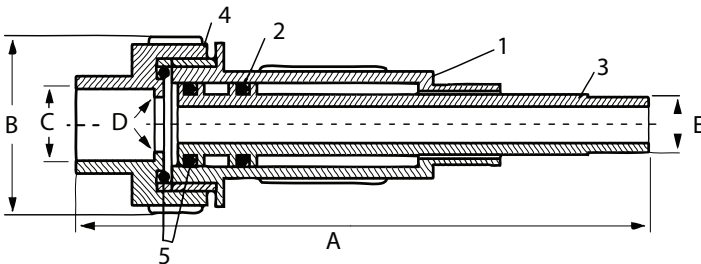

Parts & Materials

No.	Part	Material
1	Ring	PVC
2	O-ring	NBR
3	plunger	PVC
4	Nut	PVC

Dimensions

Size	Part Number	Weight LB	A - (min) Inches	A - (max) Inches	B - Inches	C - Inches	D - Inches	E - Inches
½	02945200	0.33	6.66"	8.74"	1.89"	0.85"	0.84"	0.84"
¾	02945212	0.45	7.56"	9.85"	2.13"	1.06"	1.04"	1.05"
1	02945214	0.76	8.71"	11.34"	2.60"	1.33"	1.31"	1.32"
1 ¼	02945216	1.10	9.77"	12.56"	2.99"	1.67"	1.65"	1.66"
1 ½	02945218	1.32	9.85"	12.81"	3.23"	1.91"	1.89"	1.90"
2	02945220	1.81	11.81"	12.48"	3.70"	2.39"	2.37"	2.38"
2 ½	02945225	2.55	12.65"	16.89"	4.22"	2.89"	2.87"	2.88"
3	02945230	3.65	13.51"	17.61"	4.96"	3.52"	3.50"	3.50"
4	02945240	5.72	14.84"	19.35"	6.15"	4.52"	4.49"	4.50"



asc-es.com

Building connections that last™