

Building connections that last™



Series 63

PVC Compression Tee, Threaded Branch




Galvanized Compression Coupling SCI® Series 63



Features

- Max. 150 psi @ 73° F
- Certified to NSF/ANSI 14 / Annex G Lead-Free

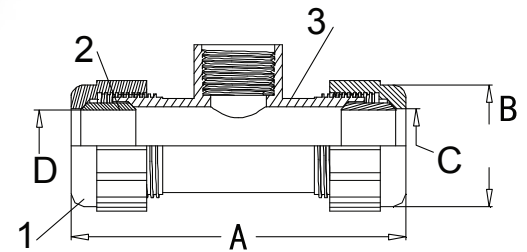

Parts & Materials

No.	Part	Material
1	Nut (2)	PVC
2	Gasket	Rubber
3	Body	PVC

Dimensions

Size	Part Number	Weight LB	A - Inches	B - Inches	C - Inches	D - Inches
1/2	02946300	0.28	5.20"	1.30"	0.89"	0.80"
3/4	02946312	0.40	5.49"	1.96"	1.13"	1.00"
3/4 x 1/2	02946390	0.40	5.49"	1.96"	1.13"	1.00"
1	02946314	0.56	5.97"	2.20"	1.35"	1.30"
1 1/4	02946316	0.83	6.30"	2.65"	1.72"	1.60"
1 1/2	02946318	0.98	6.87"	2.90"	2.00"	1.85"
2	02946320	1.33	7.63"	3.44"	2.43"	2.34"



asc-es.com


Building connections that last™

Galvanized Compression Coupling SCI® Series 63



Features

- Max. 150 psi @ 73° F
- Certified to NSF/ANSI 14 / Annex G Lead-Free

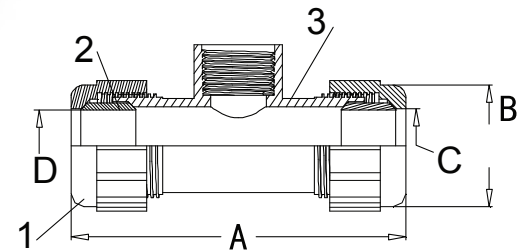

Parts & Materials

No.	Part	Material
1	Nut (2)	PVC
2	Gasket	Rubber
3	Body	PVC

Dimensions

Size	Part Number	Weight LB	A - Inches	B - Inches	C - Inches	D - Inches
1/2	02956350	0.28	5.20"	1.30"	0.89"	0.80"
3/4	02946362	0.40	5.49"	1.96"	1.13"	1.00"
1	02946364	0.56	5.97"	2.20"	1.35"	1.30"
1 1/4	0294366	0.83	6.30"	2.65"	1.72"	1.60"
1 1/2	02946368	0.98	6.87"	2.90"	2.00"	1.85"
2	02946370	1.33	7.63"	3.44"	2.43"	2.34"



asc-es.com

Building connections that last™