


# MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS

## HALF COUPLINGS

| Item ID<br>304 | Item ID<br>316 | Size   | Pkg<br>Qty | Approx<br>Weight | 1    | L    |
|----------------|----------------|--------|------------|------------------|------|------|
| SS304-64201    | SS316-64201    | 1/8"   | 25         | 0.0240           | 0.59 | 0.48 |
| SS304-64202    | SS316-64202    | 1/4"   | 25         | 0.0276           | 0.72 | 0.48 |
| SS304-64203    | SS316-64203    | 3/8"   | 25         | 0.0386           | 0.86 | 0.54 |
| SS304-64204    | SS316-64204    | 1/2"   | 25         | 0.0661           | 1.02 | 0.67 |
| SS304-64206    | SS316-64206    | 3/4"   | 25         | 0.1102           | 1.29 | 0.72 |
| SS304-64210    | SS316-64210    | 1"     | 25         | 0.1653           | 1.59 | 0.78 |
| SS304-64212    | SS316-64212    | 1 1/4" | 10         | 0.2425           | 1.91 | 0.95 |
| SS304-64214    | SS316-64214    | 1 1/2" | 10         | 0.3649           | 2.22 | 1.00 |
| SS304-64220    | SS316-64220    | 2"     | 5          | 0.6173           | 2.73 | 1.19 |
| SS304-64224    | SS316-64224    | 2 1/2" | 1          | 0.7055           | 3.17 | 1.38 |
| SS304-64230    | SS316-64230    | 3"     | 1          | 1.0582           | 3.82 | 1.52 |
| SS304-64240    | SS316-64240    | 4"     | 1          | 1.5873           | 4.83 | 1.75 |

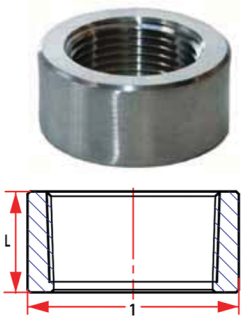

## DOMESTIC AND IMPORTED FITTINGS

Stainless steel fittings are investment castings and Trenton Pipe carries a full size range that is available in stock from 1/8" – 4" in both 304 and 316 grades of stainless steel.

All fittings are threaded to NPT standard in compliance to **ASME B1.20.1**, castings are made in accordance to **ASTM A351** and all fittings are heat treated and tested in accordance to **ASTM A262**.



**(800) 257-9559**

Fax: (866) 706-5260

[sales@trentonpipe.com](mailto:sales@trentonpipe.com)