


STANDARD PATTERN STAINLESS STEEL FITTINGS

ELBOWS - 45°

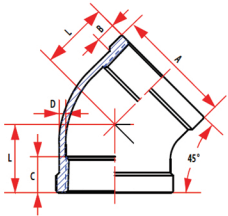

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	L	A	B	C	D
SS304-61001	SS316-61001	1/8"	25	0.0772	0.66	0.72	0.20	0.27	0.110
SS304-61002	SS316-61002	1/4"	25	0.0902	0.66	0.81	0.20	0.33	0.124
SS304-61003	SS316-61003	3/8"	25	0.1102	0.78	0.96	0.20	0.36	0.082
SS304-61004	SS316-61004	1/2"	25	0.1726	0.83	1.15	0.24	0.42	0.087
SS304-61006	SS316-61006	3/4"	25	0.2866	0.96	1.4	0.26	0.49	0.100
SS304-61010	SS316-61010	1"	10	0.4156	1.07	1.70	0.29	0.57	0.106
SS304-61012	SS316-61012	1 1/4"	10	0.6673	1.25	2.05	0.33	0.65	0.114
SS304-61014	SS316-61014	1 1/2"	5	0.8545	1.37	2.33	0.36	0.68	0.123
SS304-61020	SS316-61020	2"	5	1.3657	1.6	2.82	0.40	0.73	0.144
SS304-61024	SS316-61024	2 1/2"	1	1.7196	1.85	3.15	0.46	0.89	0.172
SS304-61030	SS316-61030	3"	1	2.5684	1.69	3.83	0.53	0.95	0.186
SS304-61040	SS316-61040	4"	1	4.3872	2.52	4.83	0.63	1.04	0.213

DOMESTIC AND IMPORTED FITTINGS

Fittings are threaded NPT in compliance to
ASME B1.20.1

Castings are threaded NPT in compliance to
ASTM A351



(800) 257-9559

Fax: (866) 706-5260
sales@trentonpipe.com