


MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS


HEX BUSHINGS

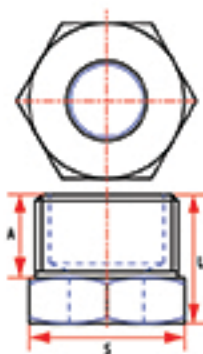

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	S	A	L
SS304-66002X01	SS316-66002X01	1/4 x 1/8"	25	0.0165	0.60	0.42	0.54
SS304-66003X01	SS316-66003X01	3/8 x 1/8"	25	0.0487	0.69	0.48	0.63
SS304-66003X02	SS316-66003X02	3/8 x 1/4"	25	0.0483	0.69	0.48	0.63
SS304-66004X01	SS316-66004X01	1/2 x 1/8"	25	0.0551	0.88	0.54	0.72
SS304-66004X02	SS316-66004X02	1/2 x 1/4"	25	0.0556	0.88	0.54	0.72
SS304-66004X03	SS316-66004X03	1/2 x 3/8"	25	0.0441	0.88	0.54	0.72
SS304-66006X01	SS316-66006X01	3/4 x 1/8"	25	0.0992	1.08	0.59	0.80
SS304-66006X02	SS316-66006X02	3/4 x 1/4"	25	0.0992	1.08	0.59	0.80
SS304-66006X03	SS316-66006X03	3/4 x 3/8"	25	0.0882	1.08	0.59	0.80
SS304-66006X04	SS316-66006X04	3/4 Xx1/2"	25	0.0716	1.08	0.59	0.80
SS304-66010X01	SS316-66010X01	1 x 1/8"	25	0.1764	1.35	0.72	0.95
SS304-66010X02	SS316-66010X02	1 x 1/4"	25	0.1874	1.35	0.72	0.95
SS304-66010X03	SS316-66010X03	1 x 3/8"	25	0.1874	1.35	0.72	0.95
SS304-66010X04	SS316-66010X04	1 x 1/2"	25	0.1775	1.35	0.72	0.95
SS304-66010X06	SS316-66010X06	1 x 3/4"	25	0.1444	1.35	0.72	0.95

MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS


HEX BUSHINGS CONT. (1)

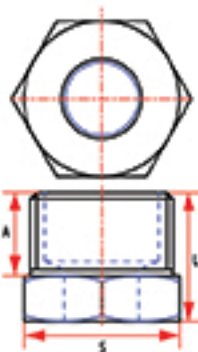

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	S	A	L
SS304-66012X01	SS316-66012X01	1-1/4x1/8"	25	0.3351	1.69	0.77	1.04
SS304-66012X02	SS316-66012X02	1-1/4x1/4"	25	0.3748	1.69	0.77	1.04
SS304-66012X03	SS316-66012X03	1-1/4x3/8"	25	0.3748	1.69	0.77	1.04
SS304-66012X04	SS316-66012X04	1-1/4 x 1/2"	25	0.3726	1.69	0.77	1.04
SS304-66012X06	SS316-66012X06	1-1/4 x 3/4"	25	0.3197	1.69	0.77	1.04
SS304-66012X10	SS316-66012X10	1-1/4 x 1"	25	0.2646	1.69	0.77	1.04
SS304-66014X02	SS316-66014X02	1-1/2x1/4"	25	0.4409	1.9	0.77	1.07
SS304-66014X03	SS316-66014X03	1-1/2x3/8"	25	0.4519	1.9	0.77	1.07
SS304-66014X04	SS316-66014X04	1-1/2 x 1/2"	25	0.4519	1.9	0.77	1.07
SS304-66014X06	SS316-66014X06	1-1/2 x 3/4"	25	0.4299	1.9	0.77	1.07
SS304-66014X10	SS316-66014X10	1-1/2 x 1"	25	0.4189	1.9	0.77	1.07
SS304-66014X12	SS316-66014X12	1-1/2 x 1-1/4"	25	0.2315	1.9	0.77	1.07
SS304-66020X02	SS316-66020X02	2x1/4"	10	0.8267	2.39	0.84	1.16
SS304-66020X03	SS316-66020X03	2x3/8"	10	0.7937	2.39	0.84	1.16
SS304-66020X04	SS316-66020X04	2 x 1/2"	10	0.8488	2.39	0.84	1.16

MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS


HEX BUSHINGS CONT. (2)

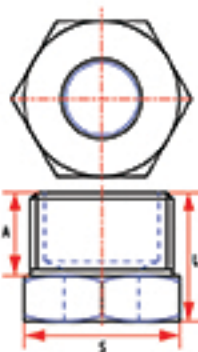

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	S	A	L
SS304-66020X06	SS316-66020X06	2 x 3/4"	10	0.8157	2.39	0.84	1.16
SS304-66020X10	SS316-66020X10	2 x 1"	10	0.7892	2.39	0.84	1.16
SS304-66020X12	SS316-66020X12	2 x 1-1/4"	10	0.6570	2.39	0.84	1.16
SS304-66020X14	SS316-66020X14	2 X 1-1/2"	10	0.5291	2.39	0.84	1.16
SS304-66024X04	SS316-66024X04	2-1/2x1/2"	5	1.4771	2.89	1.01	1.37
SS304-66024X06	SS316-66024X06	2-1/2x3/4"	5	1.4374	2.89	1.01	1.37
SS304-66024X10	SS316-66024X10	2-1/2 x 1"	5	1.4550	2.89	1.01	1.37
SS304-66024X12	SS316-66024X12	2-1/2 x 1-1/4"	5	1.2588	2.89	1.01	1.37
SS304-66024X14	SS316-66024X14	2-1/2 x 1-1/2"	5	1.1243	2.89	1.01	1.37
SS304-66024X20	SS316-66024X20	2-1/2 x 2"	5	0.8047	2.89	1.01	1.37
SS304-66030X10	SS316-66030X10	3 x 1"	5	2.2377	3.55	1.07	1.46
SS304-66030X12	SS316-66030X12	3 X 1-1/4"	5	2.1495	3.55	1.07	1.46
SS304-66030X14	SS316-66030X14	3 X 1-1/2"	5	2.1495	3.55	1.07	1.46
SS304-66030X20	SS316-66030X20	3 X 2"	5	1.6975	3.55	1.07	1.46
SS304-66030X24	SS316-66030X24	3 x2-1/2"	1	1.4403	3.55	1.07	1.46

MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS

HEX BUSHINGS CONT. (3)

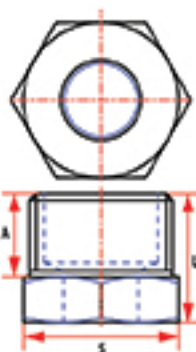

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	S	A	L
SS304-66040X12	SS316-66040X12	4x1-1/4"	1	4.0344	4.51	1.19	1.76
SS304-66040X14	SS316-66040X14	4x1-1/2"	1	3.9352	4.51	1.19	1.76
SS304-66040X20	SS316-66040X20	4 x 2"	1	3.6045	4.51	1.19	1.76
SS304-66040X24	SS316-66040X24	4 x 2-1/2"	1	3.8140	4.51	1.19	1.76
SS304-66040X30	SS316-66040X30	4 x 3"	1	2.9189	4.51	1.19	1.76

DOMESTIC AND IMPORTED FITTINGS

Stainless steel fittings are investment castings and Trenton Pipe carries a full size range that is available in stock from 1/8" – 4" in both 304 and 316 grades of stainless steel.

All fittings are threaded to NPT standard in compliance to **ASME B1.20.1**, castings are made in accordance to **ASTM A351** and all fittings are heat treated and tested in accordance to **ASTM A262**.



(800) 257-9559

Fax: (866) 706-5260

sales@trentonpipe.com