
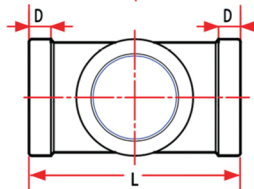


MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS

CROSSES

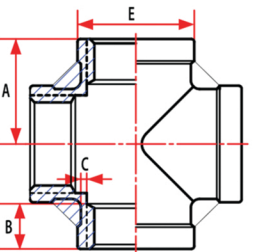

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	A	B	C	D	E	L
SS304-63601	SS316-63601	1/8"	25	0.1367	0.74	0.27	0.110	0.20	0.72	1.48
SS304-63602	SS316-63602	1/4"	25	0.1519	0.74	0.33	0.124	0.20	0.81	1.48
SS304-63603	SS316-63603	3/8"	25	0.1984	0.85	0.36	0.073	0.20	0.96	1.70
SS304-63604	SS316-63604	1/2"	25	0.3197	1.02	0.42	0.081	0.24	1.15	2.04
SS304-63606	SS316-63606	3/4"	10	0.4960	1.20	0.49	0.098	0.26	1.40	2.40
SS304-63610	SS316-63610	1"	10	0.7716	1.38	0.57	0.109	0.29	1.70	2.76
SS304-63612	SS316-63612	1 1/4"	5	1.1695	1.61	0.65	0.119	0.33	2.05	3.22
SS304-63614	SS316-63614	1 1/2"	5	1.4202	1.77	0.68	0.123	0.36	2.33	3.54
SS304-63620	SS316-63620	2"	1	2.2244	2.08	0.73	0.139	0.40	2.82	4.16
SS304-63624	SS316-63624	2 1/2"	1	2.8660	2.47	0.89	0.173	0.46	3.15	4.94
SS304-63630	SS316-63630	3"	1	4.2328	2.83	0.95	0.189	0.53	3.83	5.66
SS304-63640	SS316-63640	4"	1	7.4626	3.53	1.04	0.236	0.63	4.83	7.06

DOMESTIC AND IMPORTED FITTINGS

Stainless steel fittings are investment castings and Trenton Pipe carries a full size range that is available in stock from 1/8" – 4" in both 304 and 316 grades of stainless steel.

All fittings are threaded to NPT standard in compliance to **ASME B1.20.1**, castings are made in accordance to **ASTM A351** and all fittings are heat treated and tested in accordance to **ASTM A262**.



(800) 257-9559

Fax: (866) 706-5260

sales@trentonpipe.com