


MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS

HEXPLUGS

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	A	L	S
SS304-67601H	SS316-67601H	1/8"	25	0.0198	0.36	0.49	0.48
SS304-67602H	SS316-67602H	1/4"	25	0.0331	0.42	0.56	0.59
SS304-67603H	SS316-67603H	3/8"	25	0.0551	0.46	0.61	0.69
SS304-67004H	SS316-67004H	1/2"	25	0.0661	0.54	0.72	0.83
SS304-67006H	SS316-67006H	3/4"	25	0.1213	0.60	0.81	1.15
SS304-67010H	SS316-67010H	1"	25	0.2094	0.72	0.96	1.36
SS304-67012H	SS316-67012H	1 1/4"	25	0.3197	0.76	1.03	1.69
SS304-67014H	SS316-67014H	1 1/2"	10	0.4299	0.79	1.09	1.90
SS304-67020H	SS316-67020H	2"	10	0.6834	0.84	1.16	2.40
SS304-67024H	SS316-67024H	2 1/2"	5	1.1243	1.02	1.37	2.90
SS304-67030H	SS316-67030H	3"	5	1.8320	1.08	1.46	3.67
SS304-67040H	SS316-67040H	4"	1	3.1065	1.17	1.64	4.54

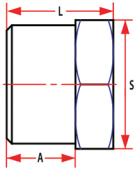

DOMESTIC AND IMPORTED FITTINGS

Stainless steel fittings are investment castings and Trenton Pipe carries a full size range that is available in stock from 1/8" – 4" in both 304 and 316 grades of stainless steel.

All fittings are threaded to NPT standard in compliance to **ASME B1.20.1**, castings are made in accordance to **ASTM A351** and all fittings are heat treated and tested in accordance to **ASTM A262**.



(800) 257-9559

Fax: (866) 706-5260

sales@trentonpipe.com