


MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS

REDUCING COUPLINGS

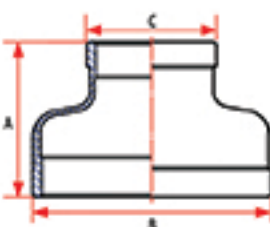

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	A	B	C
SS304-64102X01	SS316-64102X01	1/4" x 1/8"	25	0.0633	0.95	0.80	0.72
SS304-64103X01	SS316-64103X01	3/8" x 1/8"	25	0.0888	1.07	0.96	0.72
SS304-64103X02	SS316-64103X02	3/8" x 1/4"	25	0.0551	1.07	0.96	0.80
SS304-64104X01	SS316-64104X01	1/2" x 1/8"	25	0.1082	1.32	1.14	0.72
SS304-64104X02	SS316-64104X02	1/2" x 1/4"	25	0.1213	1.32	1.14	0.80
SS304-64104X03	SS316-64104X03	1/2" x 3/8"	25	0.1323	1.32	1.14	0.96
SS304-64106X01	SS316-64106X01	3/4" x 1/8"	25	0.1653	1.43	1.39	0.72
SS304-64106X02	SS316-64106X02	3/4" x 1/4"	25	0.1764	1.43	1.39	0.80
SS304-64106X03	SS316-64106X03	3/4" x 3/8"	25	0.1984	1.43	1.39	0.96
SS304-64106X04	SS316-64106X04	3/4" x 1/2"	25	0.1984	1.43	1.39	1.14
SS304-64110X01	SS316-64110X01	1" x 1/8"	25	0.2601	1.54	1.69	0.72
SS304-64110X02	SS316-64110X02	1" x 1/4"	25	0.2646	1.54	1.69	0.80
SS304-64110X03	SS316-64110X03	1" x 3/8"	25	0.2646	1.54	1.69	0.96
SS304-64110X04	SS316-64110X04	1" x 1/2"	25	0.2646	1.54	1.69	1.14
SS304-64110X06	SS316-64110X06	1" x 3/4"	25	0.2866	1.54	1.69	1.14
SS304-64112X03	SS316-64112X03	1-1/4" x 3/8"	10	0.4308	1.90	1.69	1.14
SS304-64112X04	SS316-64112X04	1-1/4" x 1/2"	10	0.4409	1.90	1.69	1.14
SS304-64112X06	SS316-64112X06	1-1/4" x 3/4"	10	0.4883	1.90	1.69	1.14
SS304-64112X10	SS316-64112X10	1-1/4" x 1"	10	0.5181	1.90	1.69	1.14
SS304-64114X03	SS316-64114X03	1-1/2" x 3/8"	10	0.5401	2.02	1.69	1.14
SS304-64114X04	SS316-64114X04	1-1/2" x 1/2"	10	0.5653	2.02	1.69	1.14
SS304-64114X06	SS316-64114X06	1-1/2" x 3/4"	10	0.5644	2.02	1.69	1.14
SS304-64114X10	SS316-64114X10	1-1/2" x 1"	10	0.6415	2.02	1.69	1.14
SS304-64114X12	SS316-64114X12	1-1/2" x 1-1/4"	10	0.6735	2.02	1.69	1.14
SS304-64120X04	SS316-64120X04	2" x 1/2"	5	0.9259	2.38	1.69	1.14
SS304-64120X06	SS316-64120X06	2" x 3/4"	5	0.8774	2.38	1.69	1.14
SS304-64120X10	SS316-64120X10	2" x 1"	5	1.0141	2.38	1.69	1.14
SS304-64120X12	SS316-64120X12	2" x 1-1/4"	5	0.9689	2.38	1.69	1.14




(800) 257-9559

Fax: (866) 706-5260

sales@trentonpipe.com

MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS

REDUCING COUPLINGS - CONT.

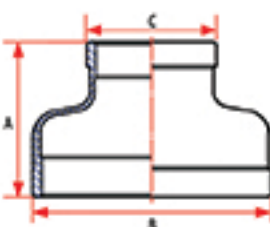

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	A	B	C
SS304-64120X14	SS316-64120X14	2" x 1-1/2"	5	1.0472	2.38	2.82	2.31
SS304-64124X10	SS316-64124X10	2-1/2" x 1"	1	1.3316	3.09	3.15	1.69
SS304-64124X12	SS316-64124X12	2-1/2" x 1-1/4"	1	1.4220	3.09	3.15	2.05
SS304-64124X14	SS316-64124X14	2-1/2" x 1-1/2"	1	1.3999	3.09	3.15	2.31
SS304-64124X20	SS316-64124X20	2-1/2" x 2"	1	1.4771	3.09	3.15	2.82
SS304-64130X10	SS316-64130X10	3" x 1"	1	1.9621	3.50	3.80	1.69
SS304-64130X12	SS316-64130X12	3" x 1-1/4"	1	2.1495	3.50	3.80	2.05
SS304-64130X14	SS316-64130X14	3" x 1-1/2"	1	2.1936	3.50	3.80	2.31
SS304-64130X20	SS316-64130X20	3" x 2"	1	2.2266	3.50	3.80	2.82
SS304-64130X24	SS316-64130X24	3" x 2-1/2"	1	2.1385	3.50	3.80	3.15
SS304-64140X20	SS316-64140X20	4" x 2"	1	3.5274	4.17	4.81	2.82
SS304-64140X24	SS316-64140X24	4" x 2-1/2"	1	3.6817	4.17	4.81	3.15
SS304-64140X30	SS316-64140X30	4" x 3"	1	3.6486	4.17	4.81	4.17

DOMESTIC AND IMPORTED FITTINGS

Stainless steel fittings are investment castings and Trenton Pipe carries a full size range that is available in stock from 1/8" – 4" in both 304 and 316 grades of stainless steel.

All fittings are threaded to NPT standard in compliance to **ASME B1.20.1**, castings are made in accordance to **ASTM A351** and all fittings are heat treated and tested in accordance to **ASTM A262**.



(800) 257-9559

Fax: (866) 706-5260

sales@trentonpipe.com