


MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS

ELBOWS - 90° STREET

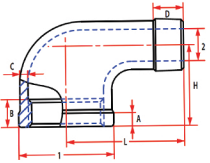

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	A	B	C	D	H	L	1	2
SS304-60201	SS316-60201	1/8"	25	0.0551	0.20	0.27	0.11	0.3	0.76	0.97	0.72	0.19
SS304-60202	SS316-60202	1/4"	25	0.0794	0.20	0.33	0.114	0.46	0.78	1.08	0.81	0.25
SS304-60203	SS316-60203	3/8"	25	0.1213	0.20	0.36	0.081	0.48	0.84	1.34	0.96	0.34
SS304-60204	SS316-60204	1/2"	25	0.1874	0.24	0.42	0.081	0.63	1.00	1.51	1.15	0.49
SS304-60206	SS316-60206	3/4"	25	0.3197	0.26	0.49	0.098	0.65	1.20	1.75	1.4	0.62
SS304-60210	SS316-60210	1"	10	0.4630	0.29	0.57	0.106	0.78	1.37	1.95	1.7	0.87
SS304-60212	SS316-60212	1 1/4"	10	0.7835	0.33	0.65	0.12	0.8	1.6	2.32	2.05	1.13
SS304-60214	SS316-60214	1 1/2"	5	1.0251	0.36	0.68	0.121	0.83	1.76	2.55	2.33	1.32
SS304-60220	SS316-60220	2"	5	1.6938	0.4	0.73	0.141	0.88	2.07	3.02	2.82	1.74
SS304-60224	SS316-60224	2 1/2"	1	2.7337	0.46	0.89	0.175	1.3	2.49	3.61	3.15	2.13
SS304-60230	SS316-61230	3"	1	4.2328	0.53	0.95	0.2	1.4	2.82	4.19	3.83	2.68
SS304-60240	SS316-60240	4"	1	7.9807	0.63	1.04	0.216	1.49	3.52	5.34	4.83	3.61

DOMESTIC AND IMPORTED FITTINGS

Stainless steel fittings are investment castings and Trenton Pipe carries a full size range that is available in stock from 1/8" – 4" in both 304 and 316 grades of stainless steel.

All fittings are threaded to NPT standard in compliance to **ASME B1.20.1**, castings are made in accordance to **ASTM A351** and all fittings are heat treated and tested in accordance to **ASTM A262**.



(800) 257-9559

Fax: (866) 706-5260

sales@trentonpipe.com