


MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS

TEES

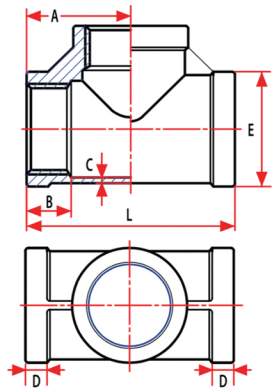

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	A	B	C	D	E	L
SS304-62001	SS316-62001	1/8"	25	0.1047	0.74	0.27	0.112	0.20	0.72	1.48
SS304-62002	SS316-62002	1/4"	25	0.1235	0.74	0.33	0.124	0.20	0.81	1.48
SS304-62003	SS316-62003	3/8"	25	0.1653	0.85	0.36	0.083	0.20	0.96	1.71
SS304-62004	SS316-62004	1/2"	25	0.2535	1.02	0.42	0.083	0.24	1.15	2.04
SS304-62006	SS316-62006	3/4"	25	0.4189	1.20	0.49	0.098	0.26	1.40	2.41
SS304-62010	SS316-62010	1"	10	0.6283	1.38	0.57	0.105	0.29	1.70	2.76
SS304-62012	SS316-62012	1 1/4"	5	0.9958	1.61	0.65	0.118	0.33	2.05	3.22
SS304-62014	SS316-62014	1 1/2"	5	1.2236	1.77	0.68	0.126	0.36	2.33	3.55
SS304-62020	SS316-62020	2"	3	1.9173	2.08	0.73	0.138	0.40	2.82	4.16
SS304-62024	SS316-62024	2 1/2"	1	2.4802	2.47	0.89	0.175	0.46	3.15	4.94
SS304-62030	SS316-62030	3"	1	3.7699	2.83	0.95	0.189	0.53	3.83	5.66
SS304-62040	SS316-62040	4"	1	6.7461	3.53	1.04	0.219	0.63	4.83	7.06

DOMESTIC AND IMPORTED FITTINGS

Stainless steel fittings are investment castings and Trenton Pipe carries a full size range that is available in stock from 1/8" – 4" in both 304 and 316 grades of stainless steel.

All fittings are threaded to NPT standard in compliance to **ASME B1.20.1**, castings are made in accordance to **ASTM A351** and all fittings are heat treated and tested in accordance to **ASTM A262**.



(800) 257-9559

Fax: (866) 706-5260

sales@trentonpipe.com