


MSS-SP114 HEAVY PATTERN STAINLESS STEEL FITTINGS

UNIONS

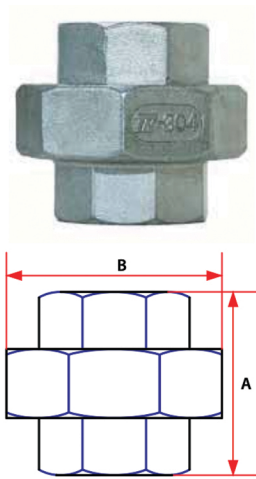

Item ID 304	Item ID 316	Size	Pkg Qty	Approx Weight	A	B
SS304-69001	SS316-69001	1/8"	25	0.1257	1.20	0.94
SS304-69002	SS316-69002	1/4"	25	0.1874	1.37	1.19
SS304-69003	SS316-69003	3/8"	25	0.2954	1.53	1.43
SS304-69004	SS316-69004	1/2"	25	0.3395	1.66	1.52
SS304-69006	SS316-69006	3/4"	25	0.6019	1.87	1.89
SS304-69010	SS316-69010	1"	10	0.7738	1.99	2.17
SS304-69012	SS316-69012	1 1/4"	5	1.0207	2.15	2.52
SS304-69014	SS316-69014	1 1/2"	5	1.347	2.30	2.84
SS304-69020	SS316-69020	2"	1	2.0194	2.62	3.44
SS304-69024	SS316-69024	2 1/2"	1	3.3289	3.06	4.12
SS304-69030	SS316-69030	3"	1	4.9163	3.33	4.73
SS304-69040	SS316-69040	4"	1	6.8761	3.66	5.99

DOMESTIC AND IMPORTED FITTINGS

Stainless steel fittings are investment castings and Trenton Pipe carries a full size range that is available in stock from 1/8" – 4" in both 304 and 316 grades of stainless steel.

All fittings are threaded to NPT standard in compliance to **ASME B1.20.1**, castings are made in accordance to **ASTM A351** and all fittings are heat treated and tested in accordance to **ASTM A262**.



(800) 257-9559

Fax: (866) 706-5260

sales@trentonpipe.com